


**B 53012** similar to DIN 6923

## Self-locking nuts

With flange and tothing

Steel 8 | zinc-plated | Cr(VI)-free | Metric thread

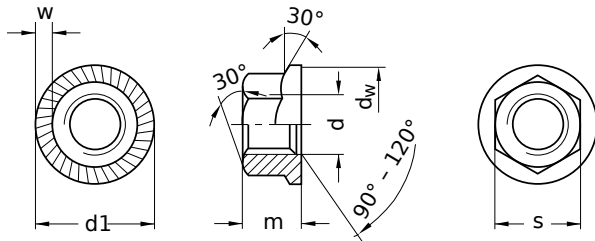

Diameter (d)	d <sub>1</sub> max.	d <sub>w</sub> min.	m		s		Pitch (P)	Tool size
			min.	max.	min.	max.		
M4	10.0	9.6	4.2	4.65	6.78	7	0.70	SW 7
M5	11.8	9.8	4.7	5.00	7.78	8	0.80	SW 8
M6	14.2	12.2	5.7	6.00	9.78	10	1.00	SW 10
M8	17.9	15.8	7.6	8.00	12.73	13	1.25	SW 13
M10	21.8	19.6	9.6	10.00	14.73	15	1.50	SW 15
M12	26.0	23.8	11.6	12.00	17.73	18	1.75	SW 18
M16	34.5	31.9	15.3	16.00	23.67	24	2.00	SW 24

All technical data refer to the measure mm

