


**DIN 125 A** similar to ISO 7089/7090

# Washers

Form A: without chamfer

Stainless steel A4 | Cr(VI)-free

Further information: DIN standard has been withdrawn

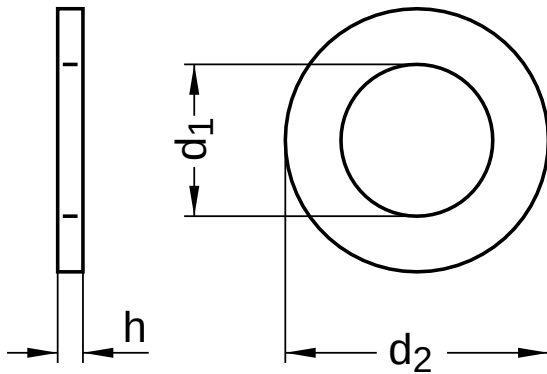

Diameter (d)	d <sub>1</sub>		d <sub>2</sub>		nominal size	h	
	min.	max.	min.	max.		min.	max.
1.7	1.7	1.84	3.70	4.0	0.3	0.25	0.35
1.8	1.8	1.94	4.20	4.5	0.3	0.25	0.35
2.2	2.2	2.34	4.70	5.0	0.3	0.25	0.35
2.5	2.5	2.64	5.70	6.0	0.5	0.45	0.55
2.7	2.7	2.84	5.70	6.0	0.5	0.45	0.55
3.2	3.2	3.38	6.64	7.0	0.5	0.45	0.55
3.7	3.7	3.88	7.64	8.0	0.5	0.45	0.55
4.3	4.3	4.48	8.64	9.0	0.8	0.70	0.90
5.3	5.3	5.48	9.64	10.0	1.0	0.90	1.10
6.4	6.4	6.62	11.57	12.0	1.6	1.40	1.80
7.4	7.4	7.62	13.57	14.0	1.6	1.40	1.80
8.4	8.4	8.62	15.57	16.0	1.6	1.40	1.80
10.5	10.5	10.77	19.48	20.0	2.0	1.80	2.20
13	13.0	13.27	23.48	24.0	2.5	2.30	2.70
15	15.0	15.27	27.48	28.0	2.5	2.30	2.70
17	17.0	17.27	29.48	30.0	3.0	2.70	3.30
19	19.0	19.33	33.38	34.0	3.0	2.70	3.30
21	21.0	21.33	36.38	37.0	3.0	2.70	3.30
23	23.0	23.33	38.38	39.0	3.0	2.70	3.30
25	25.0	25.33	43.38	44.0	4.0	3.70	4.30
28	28.0	28.33	49.38	50.0	4.0	3.70	4.30
31	31.0	31.39	55.26	56.0	4.0	3.70	4.30
34	34.0	34.62	58.80	60.0	5.0	4.40	5.60
37	37.0	37.62	64.80	66.0	5.0	4.40	5.60
40	40.0	40.62	70.80	72.0	6.0	5.40	6.60
43	43.0	43.62	76.80	78.0	7.0	6.00	8.00
46	46.0	46.62	83.60	85.0	7.0	6.00	8.00
50	50.0	50.62	90.60	92.0	8.0	7.00	9.00

All technical data refer to the measure mm

