


DIN 466
Knurled nuts

High version

Steel 05 | bright | Cr(VI)-free | Metric thread

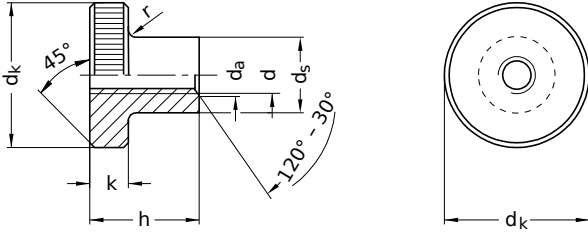

| Diameter (d) | d _a | | nominal size | d _k | | d _s | | h | | k | | r nominal size | Pitch (P) |
|-----------------|----------------|-------|--------------|----------------|-------|----------------|------|-------|------|------|------|-------------------|--------------|
| | min. | max. | | min. | max. | min. | max. | min. | max. | min. | max. | | |
| M3 | 3 | 3.45 | 12 | 11.65 | 12.35 | 5.70 | 6 | 7.14 | 7.5 | 2.25 | 2.5 | 0.5 | 0.50 |
| M4 | 4 | 4.60 | 16 | 15.65 | 16.35 | 7.64 | 8 | 9.14 | 9.5 | 3.20 | 3.5 | 0.5 | 0.70 |
| M5 | 5 | 5.75 | 20 | 19.58 | 20.42 | 9.64 | 10 | 11.07 | 11.5 | 3.70 | 4.0 | 1 | 0.80 |
| M6 | 6 | 6.75 | 24 | 23.58 | 24.42 | 11.57 | 12 | 14.57 | 15.0 | 4.70 | 5.0 | 1 | 1.00 |
| M8 | 8 | 8.75 | 30 | 29.58 | 30.42 | 15.57 | 16 | 17.57 | 18.0 | 5.70 | 6.0 | 2 | 1.25 |
| M10 | 10 | 10.80 | 36 | 35.50 | 36.50 | 19.48 | 20 | 22.48 | 23.0 | 7.64 | 8.0 | 2 | 1.50 |

All technical data refer to the measure mm

