


**DIN 7981 C** similar to ISO 7049

## Tapping screws

Button head | cross-slot phillips | form C with cone point

Stainless steel A2 | Cr(VI)-free | Thread type ST (sheet metal)

Further information: DIN-standard has been withdrawn | changed head measurements with ISO norm

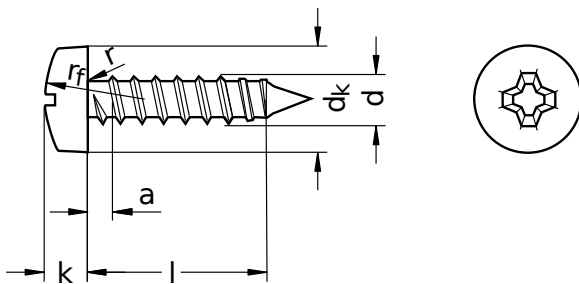

Diameter (d)	a		d <sub>k</sub>		k		rf	r	Pitch (P)	Tool size
	max.	min.	max.	min.	max.	max.				
2.2	0.8	3.90	4.2	1.55	1.80	3.4	0.3	0.8	H1	
2.9	1.1	5.30	5.6	1.95	2.20	4.4	0.4	1.1	H1	
3.5	1.3	6.54	6.9	2.35	2.60	5.4	0.5	1.3	H2	
3.9	1.3	7.14	7.5	2.55	2.80	5.8	0.5	1.3	H2	
4.2	1.4	7.84	8.2	2.75	3.05	6.2	0.6	1.4	H2	
4.8	1.6	9.14	9.5	3.25	3.55	7.2	0.7	1.6	H2	
5.5	1.8	10.37	10.8	3.65	3.95	8.2	0.8	1.8	H3	
6.3	1.8	12.07	12.5	4.25	4.55	9.5	0.9	1.8	H3	

nominal size	Length (l)	
	min.	max.
4.5	3.7	5.3
6.5	5.7	7.3
9.5	8.7	10.3
13.0	12.2	13.8
16.0	15.2	16.8
19.0	18.2	19.8
22.0	21.2	22.8
25.0	24.2	25.8

nominal size	Length (l)	
	min.	max.
32.0	30.7	33.3
38.0	36.7	39.3
45.0	43.7	46.3
50.0	48.7	51.3
60.0	58.7	61.3

All technical data refer to the measure mm



**DIN 7981 C** similar to ISO 7049

## Tapping screws

Button head | cross-slot phillips | form C with cone point

Stainless steel A2 | Cr(VI)-free | Thread type ST (sheet metal)

Diameter (d)	Length (l)												
	4.5	6.5	9.5	13	16	19	22	25	32	38	45	50	60
2.2	●	●	●	●	●								
2.9		●	●	●	●	●							
3.5			●	●	●	●	●	●					
3.9			●	●	●	●	●	●					●
4.2		●	●	●	●	●	●	●	●	●			●
4.8			●	●	●	●	●	●	●	●	●		
5.5				●	●	●	●	●	●	●			
6.3				●	●	●	●	●	●	●			

• Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

