


E 1412
EJOT®-PT screws

Button head | cross-slot phillips

Steel 10 | zinc-plated | Cr(VI)-free | Self-tapping thread

Further information: For further information and CAD-files please follow the link to the EJOT-homepage:

<http://www.ejot.com/industry>

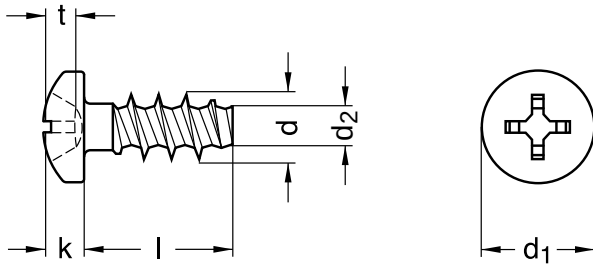

Diameter (d)	d ₁ nominal size	d ₂ nominal size	k nominal size	Pitch (P)	t		Tool size
					max.	min.	
1.8	3.2	1.04	1.2	0.35	1.00	0.70	H0
2.2	3.9	1.25	1.5	0.98	1.20	0.74	H1
2.5	4.4	1.4	1.7	1.12	1.38	0.92	H1
3	5.3	1.66	2.0	1.34	1.65	1.19	H1
3.5	6.1	1.91	2.5	1.57	1.86	1.23	H2
4	7	2.17	2.7	1.79	2.14	1.51	H2
5	8.8	2.68	3.4	2.24	2.75	2.12	H2

nominal size	Length (l)	
	min.	max.
4.5	4.12	4.88
5.0	4.62	5.38
6.0	5.62	6.38
7.0	6.55	7.45
8.0	7.55	8.45
10.0	9.55	10.45
12.0	11.45	12.55
14.0	13.45	14.55

nominal size	Length (l)	
	min.	max.
16.0	15.45	16.55
18.0	17.45	18.55
20.0	19.35	20.65
22.0	21.35	22.65
25.0	24.35	25.65
30.0	29.35	30.65
35.0	34.20	35.80
40.0	39.20	40.80

All technical data refer to the measure mm



E 1412

EJOT®-PT screws

Button head | cross-slot phillips

Steel 10 | zinc-plated | Cr(VI)-free | Self-tapping thread

Diameter (d)	Length (l)															
	4.5	5	6	7	8	10	12	14	16	18	20	22	25	30	35	40
1.8		●	●		●	●										
2.2	●	●	●		●	●	●	●	●							
2.5		●	●		●	●	●	●	●	●	●					
3			●	●	●	●	●	●	●	●	●		●	●		
3.5				●	●	●	●	●	●	●	●		●	●	●	
4					●	●	●	●	●	●	●	●	●			
5						●	●	●	●	●	●		●	●	●	●

• Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

