



E 1452
EJOT®-PT screws

Button head | torx drive

Stainless steel A2 | Cr(VI)-free | Self-tapping thread

Further information: For further information and CAD-files please follow the link to the EJOT-homepage:

<http://www.ejot.com/industry>

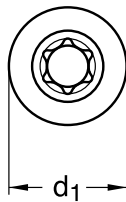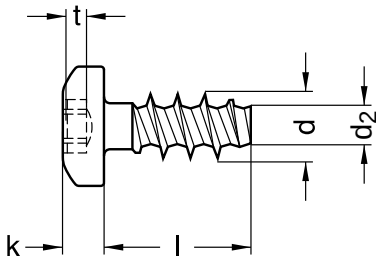

Diameter (d)	d ₁ nominal size	d ₂ nominal size	k nominal size	Pitch (P)	t		Tool size
					max.	min.	
2.5	4.1	1.4	1.6	1.12	0.85	0.70	T7
3	5.6	1.66	2.1	1.34	1.30	1.00	T10
4	7.5	2.17	2.6	1.79	1.70	1.25	T20

Length (l) nominal size
8
10
12
14

Length (l) nominal size
16
18
40

Diameter (d)	Length (l)						
	8	10	12	14	16	18	40
2.5	●						
3	●	●		●	●		
4		●	●	●		●	●

• Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

