


E 1452
EJOT®-PT screws

Button head | torx drive

Steel 10 | zinc-plated | Cr(VI)-free | Self-tapping thread

Further information: For further information and CAD-files please follow the link to the EJOT-homepage:

<http://www.ejot.com/industry>

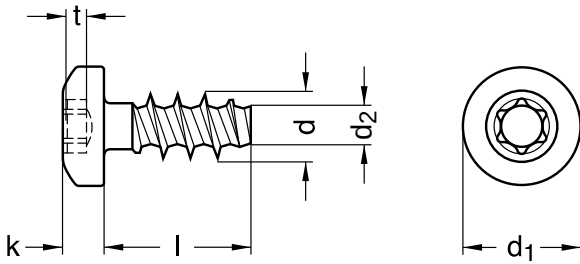

Diameter (d)	d ₁ nominal size	d ₂ nominal size	k nominal size	Pitch (P)	t		Tool size
					max.	min.	
1.8	3.6	1.04	1.3	0.35	0.85	0.70	T6
2	3.6	1.15	1.5	0.40	0.85	0.70	T6
2.2	4	1.25	1.4	0.98	0.85	0.70	T6
2.5	4.2	1.4	1.6	1.12	0.85	0.70	T7
3	5.6	1.66	2.1	1.34	1.30	1.00	T10
3.5	6.9	1.91	2.3	1.57	1.40	1.10	T10
4	7.5	2.17	2.6	1.79	1.70	1.25	T20
5	8.2	2.68	2.9	2.24	1.80	1.40	T20
6	10.8	3.19	3.8	2.69	2.00	1.60	T25

nominal size	Length (l)	
	min.	max.
5	4.62	5.38
6	5.62	6.38
8	7.55	8.45
10	9.55	10.45
12	11.45	12.55
14	13.45	14.55
16	15.45	16.55
18	17.45	18.55

nominal size	Length (l)	
	min.	max.
20	19.35	20.65
22	21.35	22.65
25	24.35	25.65
30	29.35	30.65
40	39.20	40.80

All technical data refer to the measure mm



E 1452

EJOT®-PT screws

Button head | torx drive

Steel 10 | zinc-plated | Cr(VI)-free | Self-tapping thread

Diameter (d)	Length (l)												
	5	6	8	10	12	14	16	18	20	22	25	30	40
1.8		●											
2		●	●	●									
2.2	●	●	●	●		●			●				
2.5		●	●	●	●		●						
3		●	●	●	●	●	●	●	●			●	●
3.5			●	●	●	●	●		●			●	●
4			●	●	●	●	●	●	●	●	●	●	●
5							●						
6					●							●	

• Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

