


ISO 8748

Spiral spring pins

Heavy duty

Spring steel | bright | Cr(VI)-free

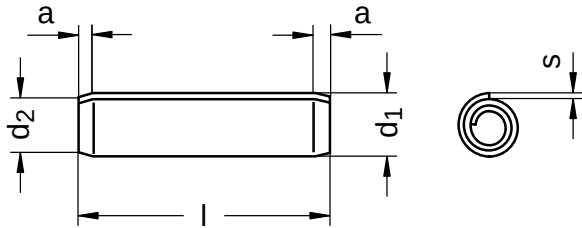

Diameter (d)	a	d ₁		d ₂	s nominal size
		min.	max.	max.	
2	0.7	2.11	2.21	1.90	0.22
3	0.9	3.12	3.25	2.90	0.33
4	1.1	4.15	4.30	3.90	0.45
5	1.3	5.15	5.35	4.85	0.56
6	1.5	6.18	6.40	5.85	0.67
8	2.0	8.25	8.55	7.80	0.90

nominal size	Length (l)	
	min.	max.
6	5.75	6.25
8	7.75	8.25
10	9.75	10.25
12	11.50	12.50
14	13.50	14.50
16	15.50	16.50
18	17.50	18.50
20	19.50	20.50
22	21.50	22.50
24	23.50	24.50

nominal size	Length (l)	
	min.	max.
26	25.50	26.50
28	27.50	28.50
30	29.50	30.50
32	31.50	32.50
36	35.50	36.50
40	39.50	40.50
45	44.50	45.50
50	49.50	50.50
55	54.25	55.75

All technical data refer to the measure mm



ISO 8748

Spiral spring pins

Heavy duty

Spring steel | bright | Cr(VI)-free

Diameter (d)	Length (l)																		
	6	8	10	12	14	16	18	20	22	24	26	28	30	32	36	40	45	50	55
2	●	●	●	●	●	●	●	●											
3		●	●	●	●	●	●	●	●		●	●	●	●					
4			●	●	●	●	●	●	●	●	●	●	●	●	●	●			
5				●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6					●	●	●	●	●	●	●	●	●		●		●	●	●
8													●	●		●	●	●	●

• Combinations available in the eShop | Other sizes on request

All technical data refer to the measure mm

