

RIVQUICK® Slotted rivets

Dome head

Note: aluminium body and aluminium mandrel

Technical information can be found on the last page.




Diameter (d)	Article number	d ₁ nominal size	d ₂ nominal size	Drilling diameter d nominal size	e	
					min.	max.
4	22047840205	4	8.3	4.2	1	8.5
	22147840160		8	4.2 - 4.4	1	5.0
	22147840250		8	4.2 - 4.4	5	11.0
4.8	22047848210	4.8	10.3	5	1	9.0
	22147848160		9.5	5.1 - 5.4	1	3.0
	22147848250		9.5	5.1 - 5.4	5	11.0

Diameter (d)	Length (l) nominal size	Head thickness	Shear force (N)	Tensile force (N)
4	20.5	1.8	600	1000
	16.0	1.2	700	800
	25.0	1.2	700	800
4.8	21.0	2.3	780	1070
	16.0	1.4	1100	1600
	25.0	1.4	1100	1600

All technical data refer to the measure mm



Symbol list

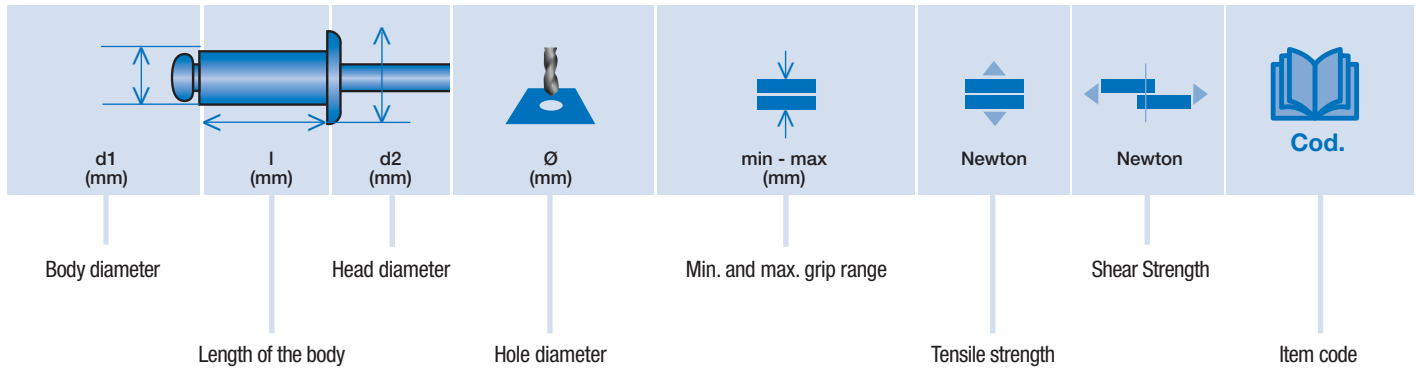

All technical data refer to the measure mm

