

RIVQUICK® Varigrip multigrip blind rivets

Dome head

Note: aluminium body and steel mandrel

Technical information can be found on the last page.




Diameter (d)	Article number	d ₁ nominal size	d ₂ nominal size	Drilling diameter d nominal size	e	
					min.	max.
3.2	22021132080	3.2	6	3.3 - 3.4	1.0	4.8
	22021132111		6.7	3.3	4.0	7.9
	22121132080		6.5	3.3 - 3.4	1.0	5.5
	22121132095		6.5	3.3 - 3.4	3.0	6.5
4	22021140100	4	8	4.1 - 4.2	1.2	6.4
	22021140127		8.3	4.1	4.0	9.5
	22121140100		8	4.1 - 4.2	1.5	6.5
	22121140170		8	4.1 - 4.2	8.0	13.0
4.8	22021148110	4.8	10	4.9 - 5.0	1.6	6.4
	22021148150		10	4.9	4.8	11.1
	22021148169		10	4.9	6.4	12.7
	22121148110		9.5	5.0 - 5.2	1.0	6.5
	22121148250		9.5	5.0 - 5.2	12.5	20.0

Diameter (d)	Length (l) nominal size	Head thickness	Shear force (N)	Tensile force (N)
3.2	8.0	1.4	600	900
	11.1	1.4	650	900
	8.0	0.9	650	900
	9.5	0.9	650	900
4	9.5	1.7	950	1500
	12.7	1.7	950	1550
	10.0	1.2	950	1550
	17.0	1.2	950	1550
4.8	10.0	2.0	1320	2000
	15.0	2.0	1320	2000
	16.9	2.0	1320	2000
	11.0	1.4	1700	2200
	25.0	1.4	1700	2200

All technical data refer to the measure mm



Symbol list

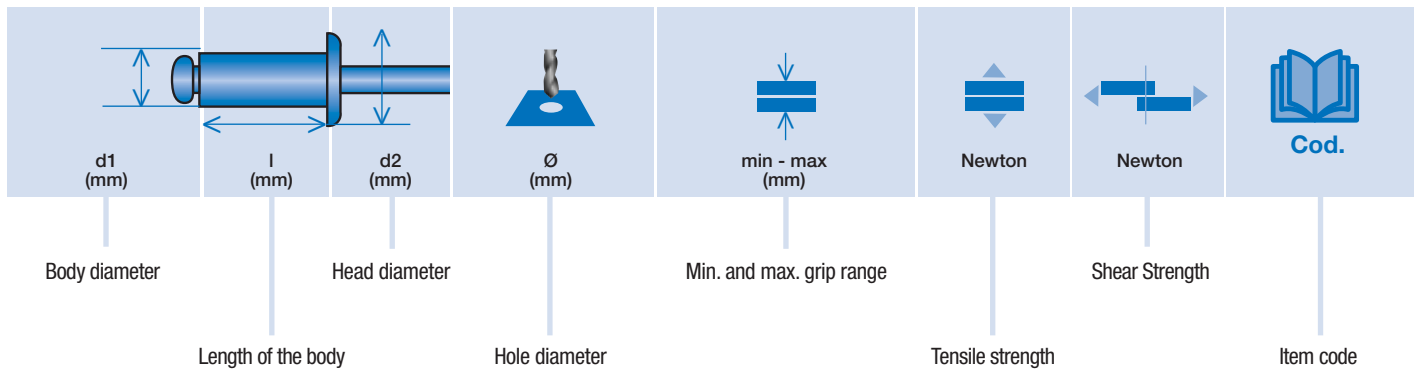

All technical data refer to the measure mm

